



Top Bioreagents Available from Thermo Fisher Scientific

Fisher Bioreagents Products Now Available with Lower Pricing


With its vast portfolio, Thermo Fisher Scientific can provide the bioreagents needed for many life science applications, including cell biology, nucleic acid, and protein workflows. Although top reagents will vary by application type, Thermo Fisher Scientific ensures high product availability of high-quality, high-purity and pre-qualified bioreagents to meet customer demand.

Whatever your field of activity — production, quality control, research, analysis or development — our team is available to provide you with the best product, service and support. Contact your Fisher Scientific sales representative or Thermo Fisher Scientific Chemical Account Manager today for more information about top bioreagents for your application.

Fisher Scientific Sales Representative

Thermo Scientific Chemical Account Manager

Please see the other side of this flier to review some of our top solvents and reagents listings

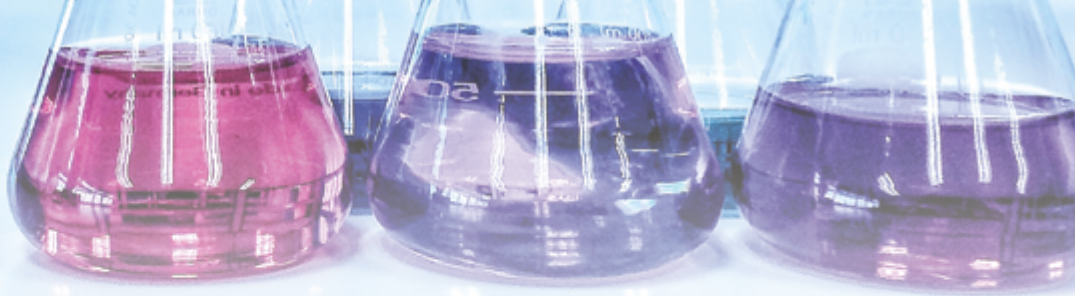

Water

Cat. No.	Description	Size
BP5611	Water, Sterile	1 L
BP2484100	Nuclease Free Water	100 ML
BP248450	Nuclease Free Water	50 ML
BP281920	Water, Molecular Biology Grade	20 L
BP28194	Water, Molecular Biology Grade	4 L
BP28201	Water, Micro Cell Culture Grade	1 L
BP2820500	Water, Micro Cell Culture Grade	500 L
BP28251	Water, Qpcr Grade	1 L


Nucleic Acid Gels

BP160500	Agarose, Low Eeo	500 G
BP2578100	Exactgene 1Kb Dna Ladder	
BP2579100	Exactgene 1Kb Plus Dna Ladder	
BP2581200	100 Bp Low Range Dna Ladder	
BP2582200	1Kb Full Range Dna Ladder	

Nucleic Acid Reagents


BP24751	10X Tris-Edta (10X Te) Ph 7.6	1 L
BP13321	Tae: Tris Acetate-Edta 50X Solt	1 L
BP13324	Tae: Tris Acetate-Edta 50X Solt	4 L
BP13331	Tbe 10 X Solution	1 L
BP13334	Tbe 10 X Solution	4 L
BP13351	10 X Tae Soln.	1 L
BP13354	10 X Tae Soln.	4 L
BP1521	Tris Base	1 KG
BP15210	Tris Base	10 KG
BP1525	Tris Base	25 KG
BP152500	Tris Base	500 G
BP1531	Tris Hydrochloride	1 KG
BP153500	Tris Hydrochloride	500 G
BP118500	Edta (Free Acid)	500 G
BP120500	Edta Disodium Salt	500 G
BP2401212	Acetic Acid, Glacial, Acs	2.5 L
BP2401500	Acetic Acid, Glacial, Acs	500 L
BP1681	Boric Acid	1 KG
BP24711	10 X Tbs Ph 7.4-10X Tris-Buffer	1 L
BP24791	10 X Ste Ph 8.0 Buffer Solution	1 L

Find it at fishersci.com

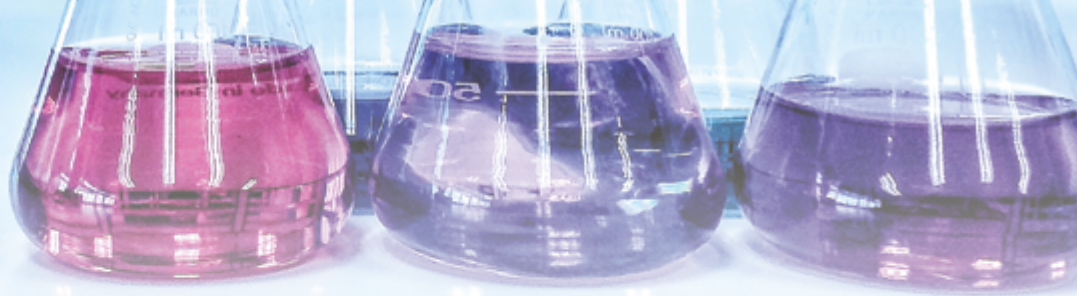

Protein Workflow

Cat. No.	Description	Size
BP1700100	Proteinase - K	100 MG
BP1700500	Proteinase - K	500 MG
BP36031	Pre-Std Rec Pro Ladder 2X500UI	
BP3603500	Pre-Std Rec Pro Ladder 500UI	
BP14061	Acrylamide: Bisacryl. 19:1 Soln	1 L
BP14081	Acrylamide: Bisacryl. 29:1 Soln	1 L
BP14101	Acrylamide: Bisacryl. 37.5:1 Sol	1 L
BP1705	Acrylamide	5 KG
BP170500	Acrylamide	500 G
BP171100	Bis-Acrylamide	100 G
BP150100	Temed	130 mL
BP15020	Temed	26 mL
BP179100	Ammonium Persulfate	100 G
BP17925	Ammonium Persulfate	25 G
BP13061	10 X Tris Glycine	1 L
BP13064	10 X Tris Glycine	4 L
BP13411	10 X Tris Glycine Sds	1 L
BP3815	Glycine	5 KG
BP381500	Glycine	500 G
BP24361	Sds 10% Soln.	1 L
BP13111	Sds 20% Soln.	1 L
BP166100	Sodium Dodecyl Sulfate	100 G
BP1665	Sodium Dodecyl Sulfate	5 KG
BP166500	Sodium Dodecyl Sulfate	500 G
BP29001	Mops 10X Electrophoresis Buf	1 L
BP2900500	Mops 10X Electrophoresis Buf	500 L
BP308100	Mops	1 L
BP308500	Mops	500 L
BP300100	Mes Monhydrate	100 G
BP315100	Tricine	100 G
BP2646100	Bicine	100G
BP16910	Urea	10 KG
BP169212	Urea	2.5 KG
BP169500	Urea	500 G
BP5715	Chaps	5 G
BP5711	Chaps	1 G

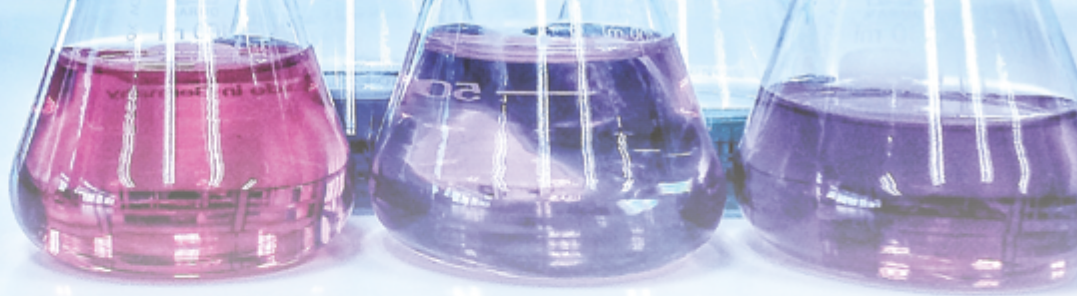

Protease Inhibitors

Cat. No.	Description	Size
BP267110	Pepstatin A	10 mg
BP267125	Pepstatin A	25 mg
BP2671100	Pepstatin A	100 mg
BP43525	Benzamidine Hcl	25 G
BP26625	Leupeptin Hemisulfate	5 mg
BP266225	Leupeptin Hemisulfate	25 mg
BP2662100	Leupeptin Hemisulfate	100 mg

Cell Culture Reagents

BP3991	Phosphate Buffered Saline	1 L
BP3994	Phosphate Buffered Saline	4 L
BP24384	Phosphate Buffered Saline	4 L
BP3101	Hepes	1 KG
BP3105	Hepes	5 KG
BP310500	Hepes	500 G
BP4101	Hepes Sodium Salt Bio	1 KG
BP410500	Hepes Sodium Salt Bio	500 G


Antibiotics

BP176025	Ampicillin Sodium Salt, Cryst.	25 G
BP26485	Carbenicillin	5 G
BP6735	G418 Sulfate	5 G
BP29571	Spectinomycin Dihydrochloride	1 G
BP904100	Chloramphenicol	100 G
BP9065	Kanamycin, Monosulfate	5 G
BP91050	Streptomycin Sulfate	50 G
BP912100	Tetracycline Hydrochloride	100 G
BP9181	Gentamycin Sulfate	1 G
BP92025	Erythromycin	25 G

Alcohols/Organics

BP82031GAL	Mol Bio Grd 70% Denatu Ethanol	1 GAL
A4594	Isopropyl Alcohol 70% V/V	4 L
A459500	Isopropyl Alcohol 70% V/V	500 ML
A4591	Isopropyl Alcohol 70% V/V	1 L
BP1150500	Iso-Amyl Alcohol Mol. Bio.	500 ML

Find it at fishersci.com

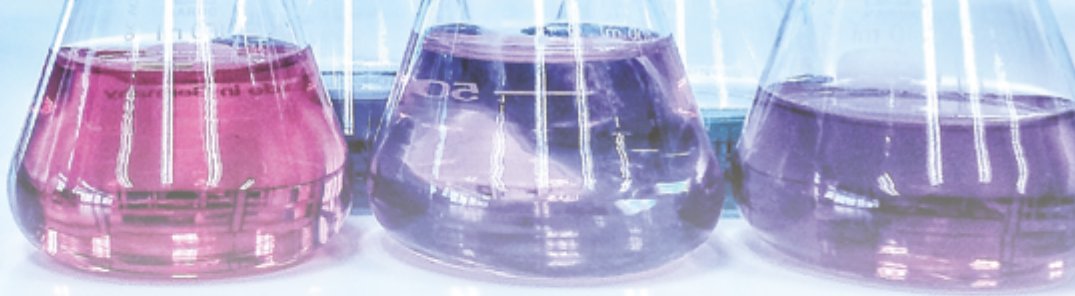

Alcohols/Organics continued

Cat. No.	Description	Size
A18P4	Acetone Acs	4 L
A18500	Acetone Certified Acs	500 ML
A412P4	Methanol Cert Acs	4 L
A412500	Methanol Certified Acs	500 L
A962P4	Alcohol Reagent Poly	4 L
A416P4	2-Propanol Acs	4 L
A416500	2 Propanol Certified Acs	500 ML
BP2618500	Isopropanol, Molecular Biology	500 ML
BP26184	Isopropanol, Molecular Biology	4 L
X3P1Gal	Xylenes Histological Grade	1 GAL
BP531500	Formaldehyde 37% Soln.	500 ML

Phenols


BP1750I400	Sat. Phenol Ph 6.6 Ñ 0.2	400 ML
BP1752I400	Phen/Chlor/I-Aml Alc Ph 6.7	400 ML

Reducing Agents

BP17225	Dithiothreitol (Dtt)	25 G
BP1725	Dithiothreitol (Dtt)	5 G
BP176100	2-Mercaptoethanol	100 G

Chemicals


BP3261	Ammonium Acetate	1 KG
BP361500	Ammonium Phosphate Dibasic	500 G
BP212212	Ammonium Sulfate	2.5 KG
BP212R1	Ammonium Sulfate	1 KG
BP510100	Calcium Chloride	100 G
BP510500	Calcium Chloride	500 G
BP2101	Cesium Chloride	1 KG
BP210100	Cesium Chloride	100 G
BP210500	Cesium Chloride	500 G
BP3501	Dextrose Anhydrous	1 KG
BP1781	Guanidine Hydrochloride	1 KG
BP178500	Guanidine Hydrochloride	500 G
BP2211	Guanidine Thiocyanate	1 KG
BP221250	Guanidine Thiocyanate	250 G

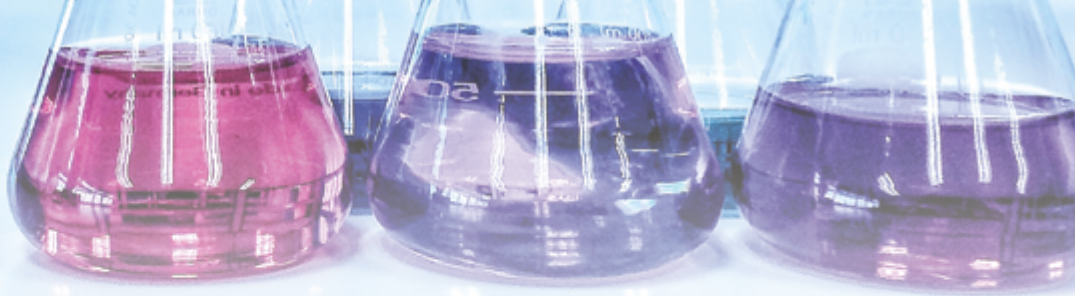

Chemicals continued

Cat. No.	Description	Size
BP2131	Magnesium Sulfate .7H ₂ O	1 KG
BP214500	Magnesium Chloride .6H ₂ O	500 G
BP3621	Potassium Phosphate Monobasic	1 KG
BP362500	Potassium Phosphate Monobasic	500 G
BP3631	Potassium Phosphate Dibasic	1 KG
BP363500	Potassium Phosphate Dibasic	500 G
BP364500	Potassium Acetate	500 G
BP365500	Potassium Carbonate	500 G
BP3661	Potassium Chloride	1 KG
BP366500	Potassium Chloride	500 G
BP367500	Potassium Iodide	500 G
BP368500	Potassium Nitrate	500 G
BP234500	Sarkosyl	500 G
BP8200100	Sds Micropellets	100 G
BP8200500	Sds Micropellets	500 G
S18125	Silver Nitrate Cert Acs	25 G
BP2546100	Silver Nitrate Molecular Bio	100 G
S181500	Silver Nitrate Cert Acs	500 G
BP3571	Sodium Carbonate	1 KG
BP3331	Sodium Acetate Anhydrous	1 KG
BP333500	Sodium Acetate, Anhydrous	500 G
BP3341	Sodium Acetate .3H ₂ O	1 KG
BP334500	Sodium Acetate .3H ₂ O	500 G
BP922i500	Sodium Azide	500 G
BP3581	Sodium Chloride	1 KG
BP35810	Sodium Chloride	10 KG
BP358212	Sodium Chloride	2.5 KG
BP3271	Sodium Citrate .2 H ₂ O	1 KG
BP327500	Sodium Citrate .2 H ₂ O	500 G
BP3281	Sodium Bicarbonate	1 KG
BP328500	Sodium Bicarbonate	500 G
BP323100	Sodium Iodide	100 G
BP3291	Sod Phos, Monobasic Anhydrous	1 KG
BP329500	Sod Phos, Monobasic Anhydrous	500 G
BP3301	Sod Phos, Monobasic Monohyd	1 KG
BP330500	Sod Phos, Mono Basic, Monohyd	500 G
BP360500	Sodium Nitrate Acs	500 G
BP26371	Sodium Persulfate, 98+%	1 KG

Find it at fishersci.com

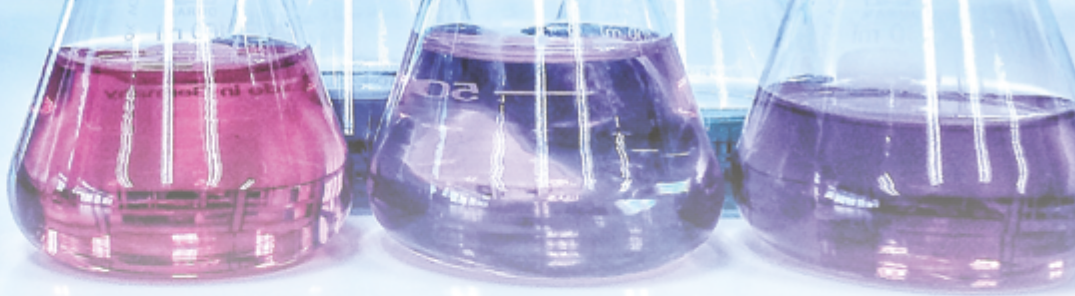

Chemicals continued

Cat. No.	Description	Size
BP3311	Sodium Phosphate Dibasic .7H ₂ O	1 KG
BP331500	Sod Phosphate Dibasic .7H ₂ O	500 G
BP3321	Sodium Phosphate Dibasic Anhyd	1 KG
BP332500	Sod Phosphate Dibasic, Anhyd	500 G
BP356100	Sodium Pyruvate	100 G
BP352500	Sodium Tartrate	500 G
BP355500	Sodium Sulfite	500 G
BP13251	20 X Ssc	1 L
BP13254	20 X Ssc	4 L
BP13284	20 X Sspe	4 L
BP151100	Triton X-100, Biotech	100 ML
BP151500	Triton X-100, Biotech	500 ML
BP337100	Tween 20, Biotech	100 ML
BP337500	Tween 20, Biotech	500 ML

pH Buffers

A142212	Hydrochloric Acid, Tech	2.5 L
SA481	Hydrochloric Acid Sol 1N Crt	1 L
SA48500	Hydrochloric Acid Sol 1N Crt	500 ML
SA561	Hydrochloric Acid, 6N	1 L
SA56500	Hydrochloric Acid 6N	500 ML
SS2551	Sodium Hydrox Sol 10N Cer	1 L
SS2661	Sodium Hydroxide Sol 1N Cert	1 L
W220	Dist Water	20 L
SB105	Buffer Pack Ph'S 4,7 & 10	500ML /EA
SB101500	Buffer Soln (Red) Ph 4	500 ML
SB107500	Buffer Soln. Ph7.00	500 ML
SB115500	Buffer Solution (Blue) Ph 10	500 ML
SE401	Electrode Storage Solution	1 L

Contact us today:

In the United States

Order online: fishersci.com

Fax an order: 1-800-926-1166

Call customer service: 1-800-766-7000

In Canada

Order online: fishersci.ca

Fax an order: 1-800-463-2996

Call customer service: 1-800-234-7437

