

Kimberly-Clark* Nitrile Exam Gloves

Best Protection.

Best Performance.

Best Value.




Exceptional
Workplaces*

Choose the Glove That's Right for You

When we say Kimberly-Clark* Nitrile Exam Gloves deliver, we've got plenty to back us up. Like extraordinary protection, performance and value. It's an impressive package of benefits that's easy to get your hands around. And it's all yours when you choose Kimberly-Clark* Purple Nitrile* Exam Gloves, Kimberly-Clark* Sterling* Nitrile Exam Gloves or Kimberly-Clark* Lavender* Nitrile Exam Gloves.


Choose the right glove for your task and budget and feel confident that you're getting outstanding quality and reliability from the brand you trust.

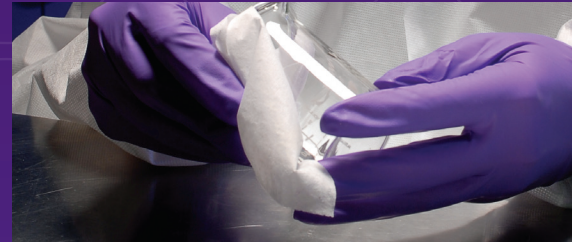

We are in the people business.
Because people are the most important asset.
They make our workplaces work.
And we make their workplaces exceptional.

Exceptional Workplaces*
Healthier, Safer, More Productive.



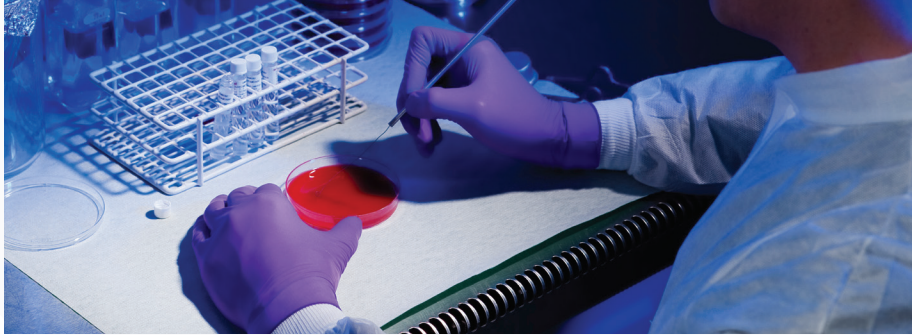

Kimberly-Clark* Purple Nitrile* Exam Gloves

Maximum protection for higher-risk procedures

Kimberly-Clark* Purple Nitrile* Exam Gloves are ideal for moderate- to high-risk settings. Purple Nitrile* is a highly durable synthetic, eliminating the risks and costs associated with latex allergies, while maximizing protection.

These durable gloves are available in 9.5 and 12 inch lengths, for maximum coverage and protection.

- 6 mil thickness
- Available in Sterile and Non-Sterile
- Cleared for use in chemotherapy
- Purple Nitrile* and Purple Nitrile-XTRA* Exam Gloves meet NFPA Standards 1999:2008
- Smartpull* box opening significantly reduces the incidence of getting more than one glove while dispensing



Product Specifications

Gauge Thickness Measurements	MM	MIL
Middle Finger	.15	5.9
Palm	.12	4.7
Cuff	.09	3.5
Average Length	242mm (9.5") XTRA* 305mm (12.0")	

Physical Properties

Before Aging	
Tensile Strength	21 MPa
Ultimate Elongation	550%
After Aging	
Tensile Strength	21 MPa
Ultimate Elongation	500%

Quality Standards

Exceeds current ASTM 6319 standard for critical defects (AQL 2.5). AQL for critical defects is 1.5.

Manufactured in accordance with Quality System ISO 9001.

Best Performance



Kimberly-Clark* Sterling* Nitrile Exam Gloves

Trusted performance

Kimberly-Clark* Sterling* Nitrile Exam Gloves provide excellent fit and feel compared to natural rubber latex, excellent comfort and tactile sensitivity, and an excellent durable barrier in a latex-free glove.

Kimberly-Clark's manufacturing process boosts the tensile strength of nitrile – the force required to break through the glove – to increase its already superior barrier protection qualities.

The process allows a reduction in glove thickness, which means that less force is required to stretch the material. That provides a latex-free glove with the dexterity and sensitivity of natural rubber latex.



- 3.5 mil thickness
- 9.5 and 12 inch lengths
- Available in Sterile and Non-Sterile
- Cleared for use in chemotherapy
- Sterling* and Sterling* NITRILE-XTRA* Exam Gloves meet NFPA Standards 1999:2008
- Smartpull* box opening significantly reduces the incidence of getting more than one glove while dispensing

Smartpull* Dispenser Box



Smartpull* dispensing incorporates 2 separate openings on the box. The first, smaller opening is used when the box is full and helps control dispensing to lessen waste from dropped gloves or multiple dispensing. When the box is half empty, the second, larger opening allows easier access to the gloves. In addition, the dispensing box also provides up to a 33% waste savings.

Product Specifications

Gauge Thickness Measurements	MM	MIL
Middle Finger	.09	3.5
Palm	.08	3.1
Cuff	.07	2.8
Average Length	242mm (9.5") XTRA* 305mm (12.0")	

Physical Properties

Before Aging	
Tensile Strength	42 MPa
Ultimate Elongation	650%
After Aging	
Tensile Strength	38 MPa
Ultimate Elongation	550%

Quality Standards

Exceeds current ASTM Standards for critical defects, tensile strength and puncture resistance.

Manufactured in accordance with Quality System ISO 9001.



Best Value

Kimberly-Clark* Lavender* Nitrile Exam Gloves

Everyday comfort, durability and affordability

Our Kimberly-Clark* Lavender* Nitrile Exam Gloves have the protective properties required for excellent performance across a wide range of applications, yet are more economical than standard nitrile gloves, providing the protection of nitrile at an everyday latex price.

Kimberly-Clark researchers have developed a glove that's thinner, lighter and more economical than standard nitrile, yet retains the protective properties required for excellent performance across a wide range of tasks.

Because the Kimberly-Clark* Lavender* Nitrile Exam Gloves are packaged as 250 gloves/box they generate less waste than typical latex gloves.

- 150% more gloves per case
- 2.8 mil thickness
- Smartpull* box opening significantly reduces the incidence of getting more than one glove while dispensing



Smartpull*
Dispenser Box

Product Specifications

Gauge Thickness Measurements	MM	MIL
Middle Finger	.07	2.8
Palm	.05	2.0
Cuff	.04	1.6
Average Length	242mm (9.5")	

Physical Properties

After Aging	
Tensile Strength	24 MPa
Ultimate Elongation	550%

Quality Standards

Exceeds current ASTM Standards for critical defects, tensile strength and puncture resistance.
Manufactured in accordance with Quality System ISO 9001.

Features

- Natural rubber latex-free
- Ambidextrous
- Beaded cuff
- Textured fingertips
- AQL 1.5

Best Protection

Kimberly-Clark® Purple Nitrile® Exam Gloves

Description	Color	X-Small	Small	Medium	Large	X-Large	Gloves/Boxes	Total/Case
Kimberly-Clark® Purple Nitrile® Exam Gloves 9.5" Ambi	Purple	55080	55081	55082	55083	55084	100/10 (XL - 90/10)	1000 (XL - 900)
Kimberly-Clark® Purple Nitrile-Xtra® Exam Gloves 12" Ambi	Purple	55090	50601	50602	50603	50604	50/10	500

Specific chemical resistance data can be found at: www.kc-safety.com/chemicalbarrierdata

Kimberly-Clark® Purple Nitrile® Sterile Exam Gloves

Description	Color	Small	Medium	Large	Gloves/Boxes	Total/Case
Kimberly-Clark® Purple Nitrile® Sterile Single Exam Gloves 9.5" Ambi	Purple	52101	52102	52103	100/4	400
Kimberly-Clark® Purple Nitrile® Sterile Pairs Exam Gloves 9.5" Ambi	Purple	55091	55092	55093	50 pairs/4	200 pairs

Best Performance

Kimberly-Clark® Sterling® Nitrile Exam Gloves

Description	Color	X-Small	Small	Medium	Large	X-Large	Gloves/Boxes	Total/Case
Kimberly-Clark® Sterling® Nitrile Exam Gloves 9.5" Ambi <i>(Replaces 55085-55089)</i>	Sterling	50705	50706	50707	50708	50709	200/10 (XL - 170/10)	2000 (XL - 1700)
Kimberly-Clark® Sterling® Nitrile-Xtra® Exam Gloves 12" Ambi	Sterling	53137	53138	53139	53140	53141	100/10	1000

Specific chemical resistance data can be found at: www.kc-safety.com/chemicalbarrierdata

Kimberly-Clark® Sterling® Nitrile Sterile Exam Gloves

Description	Color	Small	Medium	Large	Gloves/Boxes	Total/Case
Kimberly-Clark® Sterling® Nitrile Sterile Pairs Exam Gloves 9.5" Ambi	Sterling	53130	53131	53132	50 pairs/4	200 pairs

Best Value

Kimberly-Clark® Lavender® Nitrile Exam Gloves

Description	Color	X-Small	Small	Medium	Large	X-Large	Gloves/Boxes	Total/Case
Kimberly-Clark® Lavender® Nitrile Exam Gloves 9.5" Ambi	Lavender	52816	52817	52818	52819	52820	250/10 (XL = 230/10)	2500 (XL = 2300)



Good for your business,
good for the planet.

The Rightcycle® Program makes it easy to recycle challenging products like cleanroom garments and gloves into a variety of useful, eco-friendly products. For more information, email rightcycle@kcc.com.

Our Guarantee

Your total satisfaction means everything to us. If, for any reason, our products do not meet your expectations, Kimberly-Clark will reimburse you for your initial purchase, via FREE product, for up to \$1,000. For more information on KIMBERLY-CLARK PROFESSIONAL®, visit us online at www.kcprofessional.com, contact your Kimberly-Clark Sales Representative, or call us at 1-888-346-GOKC (4652).

‡ Guarantee extended to consuming end-user accounts only.

Kimberly-Clark warrants that its products (1) comply with K-C's standard specifications as of the delivery date to K-C's authorized distributors/direct purchasers except for auto-darkening filters which shall be warranted for two years from date of end-user purchase (verified by valid sales receipt) and powered air purifying respirators which shall be warranted for one year from date of end-user purchase (verified by valid sales receipt); (2) comply with all K-C labeling representations; and (3) are manufactured in compliance with all applicable federal, state, and local laws in effect at the time and place of manufacture of the products. **THIS WARRANTY IS IN LIEU OF ALL OTHER WARRANTIES, EXPRESS OR IMPLIED, INCLUDING ANY WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE.** K-C is not liable for any kind of special, incidental, or consequential damages. K-C's liability for breach of contract, tort or other cause of action shall not exceed the product purchase price. Purchasers and users are deemed to have accepted the above warranty and limitation of liability, and cannot change the terms by verbal agreement or by any writing not signed by K-C. To the extent required by applicable law, K-C does not limit its liability for death/injury resulting from K-C's negligence.

®/™ Trademarks of Kimberly-Clark Worldwide, Inc. or its affiliates. Marques déposées de Kimberly-Clark Worldwide, Inc. ou de ses filiales. The COLOR PURPLE is a Registered Trademark of KCWW. COLOR GREY and COLOR Lavender - Trademarks of KCWW. © KCWW. Printed in the U.S.A. S160 P14-1545 6/14



Exceptional
Workplaces®